



Bare copper, Type P190 Under ground

UNDER GROUND: Bare copper, Type P190

DIMENSION DATA

DRAKA NORSK KABEL no.	Area [mm ²]	Diameter Overall [mm]	Weight of cable approx. [kg/km]
130940	25	6,4	222
130950	35	7,6	310
130957	50	9,0	430
130960	70	10,9	620
130970	95	12,6	845
130975	120	14,2	1080

INSTALLATION DATA

Type mm ²	Overall diameter mmØ	Minimum during installation mmØ	bending radius fixed installed mmØ	Max pulling tension N
25	6,4	64	39	1250
35	7,6	76	45	1750
50	9,0	90	54	2500
70	10,9	109	66	3500
95	12,6	126	78	4750
120	14,2	142	90	6000




Bare copper, Type P190 Under ground

CABLE DRAWING: Bare copper

Cable type P190

Construction according to IEC 228 class 2

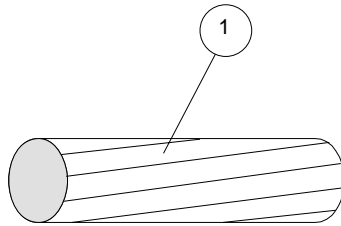

Cable drawing for indication only

1. Annealed stranded copper